

Rexnord® TableTop® and MatTop® Chains



7956 TAB MatTop® Chain



Rexnord® 7956 TAB Series RexFlex™ MatTop® Chain Is the strongest side-flexing chain on the market. It actually has the same strength rating in the curves as it does in the straights! Ideal for all your heavy-duty case conveying applications. If that wasn't enough, an aggressively tight turn radius (2.0 x Chain Width) sets the 7956 further apart from the competition. Our patented Rexnord High Performance (HP) Material offers the lowest friction available in the industry. With RexFlex chain you focus your time on profits, not your conveyor layout.

Contact your local Rexnord Sales Representative, a Rexnord Industrial Distributor in your area, or visit our Web site at www.rexnord.com for more information.

Available in a full range of widths to specifically tailor to your conveying requirements: 6 in (152.4 mm), 12 in (304.8 mm), 15 in (381.0 mm), 18 in (457.2 mm), 24 in (609.6 mm), 30 in (762.0 mm)

Features & Benefits

- Highest working load of any side-flexing MatTop® style chain or belt available
- Innovative design provides the same high strength features in corners as well as straight sections
- 16% open area for applications where air or water flow through is required
- Excellent for use in food processing applications (both raw and packaged foods) due to the heavy-duty and cleanable chain design
- Designed to convey products continuously around corners as well as straight sections eliminating potential product damage due to multiple transfers
- Minimizes floor space due to flexible design
- Small 1.25 in (31.8 mm) pitch design allows smooth product transfers
- Unique integrated TAB design holds the pin in place and can be easily removed
- TAB feature can be used to for slight inclines and returning the chain, reducing top surface wear
- Multiple sprocket pocket design offers unparalleled chain / sprocket interaction as well as flexibility in conveyor design
- Sprockets and corner tracks are available

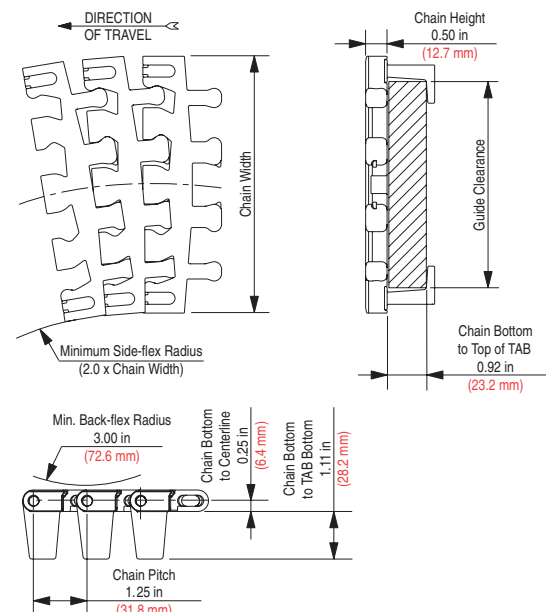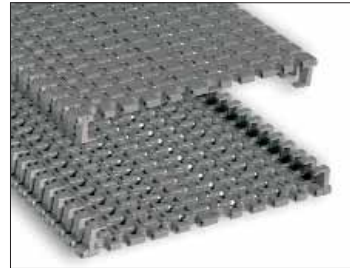

TableTop, MatTop, and Rexnord are registered trademarks, and HP and RexFlex are trademarks of Rexnord Industries, LLC. All rights reserved.

WORLDWIDE CUSTOMER SERVICE

AUSTRALIA

Rexnord Australia Pty. Ltd.
Picton, New South Wales
Phone: 61-2-4677-3811
Fax: 61-2-4677-3812

BRAZIL

Rexnord Correntes Ltda.
Sao Leopoldo - RS
Phone: 55-51-579-8022
Fax: 55-51-579-8029

CANADA

Rexnord Canada Ltd.
Scarborough, Ontario
Phone: 1-416-297-6868
Fax: 1-416-297-6873

CHINA

Rexnord China
Shanghai, China
Phone: 86-21-62701942
Fax: 86-21-62701943

EUROPE

Rexnord NV/SA
Mechelen, Belgium
Phone: 32-15-443811
Fax: 32-15-443860

Rexnord Kette GmbH
Betzdorf, Germany
Phone: 49-2741-2840
Fax: 49-2741-284-385

LATIN AMERICA

Rexnord International, Inc.
Milwaukee, Wisconsin
Phone: 1-414-643-2366
Fax: 1-414-643-3222
E-mail: international2@rexnord.com

MEXICO

Rexnord S.A. de C.V.
Queretaro, Qro.
Phone: 52-442-218.5000
Fax: 52-442-218-1090

SINGAPORE

Rexnord International, Inc.
Singapore City, Singapore
Phone: 65-6338-5622
Fax: 65-6338-5422

UNITED STATES

Customer Service
Phone: 1-866-REXNORD
(1-866-739-6673)
Fax: 1-614-675-1898
E-mail: rexnordcs(state)@rexnord.com
Example: rexnordcssohio@rexnord.com

ALL COUNTRIES NOT LISTED

Rexnord International, Inc.
Milwaukee, Wisconsin
Phone: 1-414-643-2366
Fax: 1-414-643-3222
E-mail: international1@rexnord.com